

# Hexagon Socket Head Cap Screws (Steel·SUS)

-Sold by the Pack-

Similar Products Comparison Points | Not RoHS Compliant / GB Standard


When ordering, select Part Number and Values from Selection Steps ①~③.

Ordering Example	Part Number (①Type-②M) - ③L
	PACK-CCB3 - 6
	PACK-CSCB6 - 10

## Hexagon Socket Head Cap Screws



Type	Material	Surface Treatment	Hardness	Strength Class
PACK-CCB	SCM435	Black Oxide	39~44HRC	12.9
PACK-CSCB	SUS304	-	-	A2-70

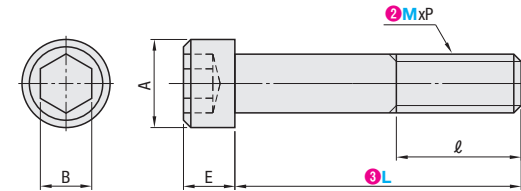

MxP (Coarse)	A	E	B
3x0.5	5.5	3	2.5
4x0.7	7	4	3
5x0.8	8.5	5	4
6x1.0	10	6	5
8x1.25	13	8	6
10x1.5	16	10	8

### [Steel]

#### Pack

Part Number	①Type	②M-③L	ℓ	Qty. / Pack
PACK-CCB	3-	5	Studs - Fully Threaded	100 pcs.
		6		
		8		
		10		
		12		
		16		
	4-	6	Studs - Fully Threaded	
		8		
		10		
		12		
		16		
		20		
	5-	8	Studs - Fully Threaded	
		10		
		12		
		16		
		20		
		25		

### [Stainless Steel]

#### Pack

Part Number	①Type	②M-③L	ℓ	Qty. / Pack	
PACK-CCB	6-	10	Studs - Fully Threaded	100 pcs.	
		12			
		16			
		20			
		25			
		30			
	8-	16			Studs - Fully Threaded
		20			
		25			
		30			
		35			
		40			

Part Number	①Type	②M-③L	ℓ	Qty. / Pack	
PACK-CSCB	3-	6	Studs - Fully Threaded	100 pcs.	
		8			
		10			
		12			
		16			
		20			
	4-	6			Studs - Fully Threaded
		8			
		10			
		12			
		16			
		20			
5-	8	Studs - Fully Threaded			
	10				
	12				
	16				
	20				
	25				

① This product is sold by the package.  
For Qty. per Package of each size, refer to above Specification Table.  
② When placing an order, please specify number of packages.  
1 package will be delivered for an order for 1.

# Hexagon Socket Set Screws / Hexagon Socket Button Head Cap Screws

-Sold by the Pack-

Similar Products Comparison Points | Not RoHS Compliant / GB Standard


When ordering, select Part Number and Values from Selection Steps ①~③.

Ordering Example	Part Number (①Type-②M) - ③L
	PACK-CMSSK3 - 6
	PACK-CSBCB5 - 10

## Hexagon Socket Set Screws



Type	Material	Hardness	Surface Treatment
PACK-CMSSK	SCM435 Equivalent	45~53HRC	Black Oxide

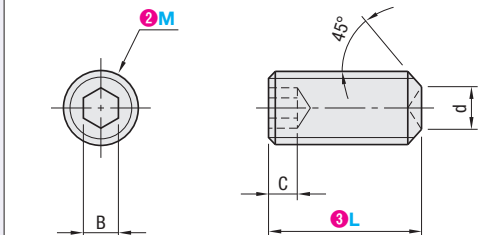

MxP (Coarse)	B	C (Min.)	d (Max.)
3x0.5	1.5	1.2	2
4x0.7	2	1.5	2.5
5x0.8	2.5	2	3.5

Part Number	①Type	②M-③L	Qty. / Pack
PACK-CMSSK	3-	3	100 pcs.
		4	
		5	
		6	
		8	
		10	
	4-	4	
		5	
		6	
		10	


Part Number	①Type	②M-③L	Qty. / Pack
PACK-CMSSK	5-	5	100 pcs.
		6	
		8	
		10	
		10	

① This product is sold by the package.  
For Qty. per Package of each size, refer to left-hand Specification Table.  
② When placing an order, please specify number of packages.  
1 package will be delivered for an order for 1.

## Hexagon Socket Button Head Cap Screws



Type	Material	Strength Class
PACK-CSBCB	SUS304	A2-50

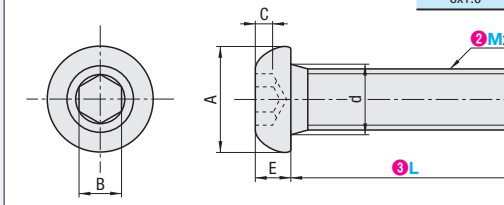

MxP (Coarse)	A	E	B	C (Min.)	d
3x0.5	5.7	1.65	2	1.04	3.6
4x0.7	7.6	2.2	2.5	1.3	4.7
5x0.8	9.5	2.75	3	1.56	5.7
6x1.0	10.5	3.3	4	2.08	6.8

Part Number	①Type	②M-③L	Qty. / Pack
PACK-CSBCB	3-	6	150 pcs.
		8	
		10	
		12	
	4-	6	
		8	
		10	
		12	

Part Number	①Type	②M-③L	Qty. / Pack
PACK-CSBCB	5-	10	100 pcs.
		12	
		20	
	6-	10	
		12	
		20	

① This product is sold by the package.  
For Qty. per Package of each size, refer to left-hand Specification Table.  
② When placing an order, please specify number of packages.  
1 package will be delivered for an order for 1.