


Note that, for some of the types shown here, order might be unable to be received by the MISUMI Thailand, Malaysia, Indonesia, and/or India offices.

Phillips Flat Head Screws

Stainless Steel (Available in Box)



Type	Material
BOX-SFBJ	SUS304 Equivalent

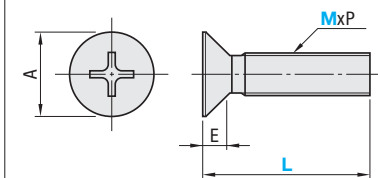

MxP (Coarse)	A	E	Phillips No.
2 x0.4	4	1.2	1
2.5x0.45	5	1.45	1
2.6x0.45	5.2	1.5	1
3 x0.5	6	1.75	2
4 x0.7	8	2.3	2
5 x0.8	10	2.8	2
6 x1.0	12	3.4	3

Can be ordered as a separate item. P230

Please specify in box quantity when ordering.
One box is shipped for an order of 1.

Ordering Example	Part Number
	BOX-SFBJ5-10

Box package is cost-saving for in-house stock or when large quantities are needed.

Part Number		Unit Price 1 to 10 boxes		Pcs./ Box
Type	M-L	Price per pkg.	1 Box	
BOX-SFBJ (Stainless Steel)	2- 3			2,000 pcs./box
	4			
	5			
	6			
	8			
	2.5- 3			
	4			
	5			
	6			
	8			
	10			
	2.6- 3			1,000 pcs./box
	4			
	5			
	6			
	8			
	10			
	3- 5			500 pcs./box
	6			
	8			
	10			
	4- 5			300 pcs./box
	6			
	8			
	10			
	5- 8			
	10			
	12			
	15			
	6-10			300 pcs./box
	12			
	15			
	15			

Phillips Flat Head Screws / Phillips Low Flat Head Screws

Single Item Sale

Phillips Flat Head Screws

Type	Material	Surface Treatment
BFBJ	SWCH Equivalent	Trivalent Chromate
SFBJ	SUS304 Equivalent	-

MxP (Coarse)	A	E	Phillips No.
2x0.4	4	1.2	1
2.5x0.45	5	1.45	1
2.6x0.45	5.2	1.5	1
3x0.5	6	1.75	2
4x0.7	8	2.3	2
5x0.8	10	2.8	2
6x1.0	12	3.4	3

BFBJ (Trivalent Chromate)

Part Number		Unit Price	Volume Discount Rate		
Type	M - L	1 ~ 29 pc(s).	30 ~ 99 pcs.	100 ~ 299 pcs.	300 ~ 500 pcs.
BFBJ	2 - 3				
	4				
	5				
	6				
	8				
	3 - 4				
	5				
	6				
	8				
	10				
	12				
	4 - 5				
	6				
	8				
	10				
	12				
	15				
	5 - 6				
	8				
	10				
	12				
	15				
	20				
	6 - 8				
	10				
	12				
	15				
	20				

Ordering Example	Part Number
	SFBJ4-10

SFBJ (Stainless Steel)

Part Number		Unit Price	Volume Discount Rate			
Type	M - L	1 ~ 29 pc(s).	30 ~ 99 pcs.	100 ~ 149 pcs.	150~ 500 pcs.	
SFBJ	2 - 3					
	4					
	5					
	6					
	8					
	2.5 - 3					
	4					
	5					
	6					
	8					
	10					
	2.6 - 3					
	4					
	5					
	6					
	8					
	10					
	3 - 4					
	5					
	6					
	8					
	10					
	12					
	15					
	20					
	4 - 5					
	6					
	8					
	10					
	12					
	15					
	5 - 6					
	8					
	10					
	12					
	15					
20						
6 - 8						
10						
12						
15						
20						

Phillips Low Flat Head Screws

Type	Material	Surface Treatment
TSARA	SWCH Equivalent	Trivalent Chromate
TSARAS	SUS304 Equivalent	-

MxP (Coarse)	A	E	Phillips No.
3x0.5	5	1.3	1
4x0.7	6	1.4	2
5x0.8	8	1.9	2
6x1.0	10	2.4	2

TSARA (Trivalent Chromate)

Part Number		Unit Price	Volume Discount Rate			
Type	M - L	1 ~ 19 pc(s).	20 ~ 99 pcs.	100 ~ 199 pcs.	200 ~ 500 pcs.	
TSARA	3 - 5					
	6					
	8					
	10					
	12					
	15					
	4 - 6					
	8					
	10					
	12					
	15					
	20					
	25					
	30					
	5 - 8					
	10					
	12					
	15					
	20					
	25					
	30					
	6 - 10					
	12					
	15					
	20					
	25					
	30					

Ordering Example	Part Number
	TSARAS-10

TSARAS (Stainless Steel)

Part Number			Unit Price	Volume Discount Rate			
Type	M	- L	1 ~ 19 pc(s).	20 ~ 99 pcs.	100 ~ 199 pcs.	200 ~ 500 pcs.	
TSARAS	4	- 6					
		8					
		10					
		12					
		15					
		20					
		25					
		30					
	5	- 8					
		10					
		12					
		15					
		20					
		25					
		30					
	6	- 10					
		12					
		15					
		20					
		25					
		30					

Ordering Example	Part Number
	TSARAS-10