


DIN
TYPE

DIN TYPE GUIDE PILLAR

— OIL GROOVE / STRAIGHT TYPE —



D—GPM011

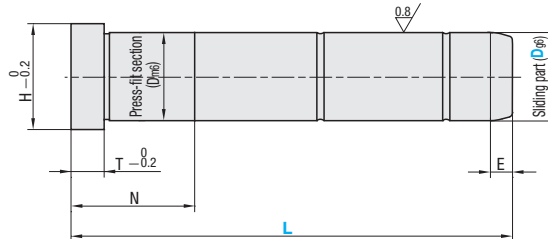

M 20Cr
H 56HRC~

Sliding part Dg6	Press-fit section Dm6	E	T	H	N	Part No.		L
						Type	D	
18	18	-0.006 -0.017	+0.018 +0.007	8	27	D—GPM011	18	80 100
					36			120
					46			140 160
					56			180 200 220
					76			80 100
20	20	-0.007 -0.020	+0.021 +0.008	15	27	20	100	
					36		120	
					46		140 160	
					56		180 200 220	
					76		80 100	
22	22	-0.007 -0.020	+0.021 +0.008	15	36	22	120 140	
					46		160 180	
					56		200 220 240 280	
					76		100	
					96		120 140	
24	24	-0.009 -0.025	+0.025 +0.009	15	36	24	120 140	
					46		160 180	
					56		200 220 240 280	
					76		120 140 160 180 200	
					96		220 240 280 320 360	
30	30	-0.009 -0.025	+0.025 +0.009	10	36	30	120 140 160 180 200	
					46		220 240 280 320 360	
					56		200 220 240 280 320 360	
					76		120 140 160 180 200 220	
					96		240 280 320 360	
32	32	-0.009 -0.025	+0.025 +0.009	10	36	32	200	
					46		240	
					56		300 360	
					76			
					96			
40	40	-0.009 -0.025	+0.025 +0.009	10	36	40	200	
					46		240	
					56		300 360	
					76			
					96			



Order

Part No. — D — L
D—GPM011 — 18 — 80



Days
to Ship

15 Days



Price

Order / Quote:

WOS: <https://in.misumi-ec.com/>
TEL:+91-124-468-8800 E-mail:cs@misumi.co.in

