


SHOULDER BOLTS / STOP BOLTS

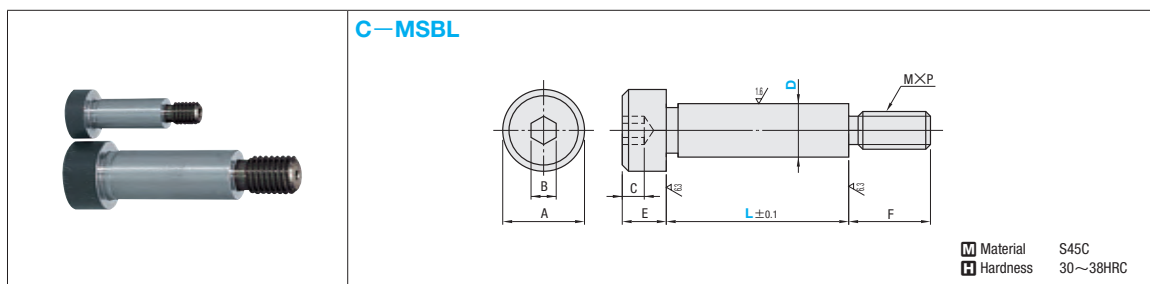

		A	B	C	E	F	M×P
6	0 -0.02	10	3	2.5	4.5	9.75	M 5×0.8
8		13	4	3	5.5	11.25	M 6×1.0
10		16	5	4	7	13.25	M 8×1.25
12		18	6	5	8	16.25	M10×1.5
16		24	8	7	10	18.25	M12×1.75

Part No.		L															
Type	D																
C-MSBL	6	12	16	20	25	30	35	40	45	50	55						
	8	12	16	20	25	30	35	40	45	50	55	60	65	70	75	80	85
	10			20	25	30	35	40	45	50	55	60	65	70	75	80	85
	12			20	25	30	35	40	45	50	55	60	65	70	75	80	85
	16					30	35	40	45	50	55	60	65	70	75	80	85



Order

Part No. — L
C-MSBL 10 — 30




Days to Ship 6 Days



Price

Order / Quote:

WOS: <https://in.misumi-ec.com/>
TEL: +91-124-468-8800 E-mail: cs@misumi.co.in

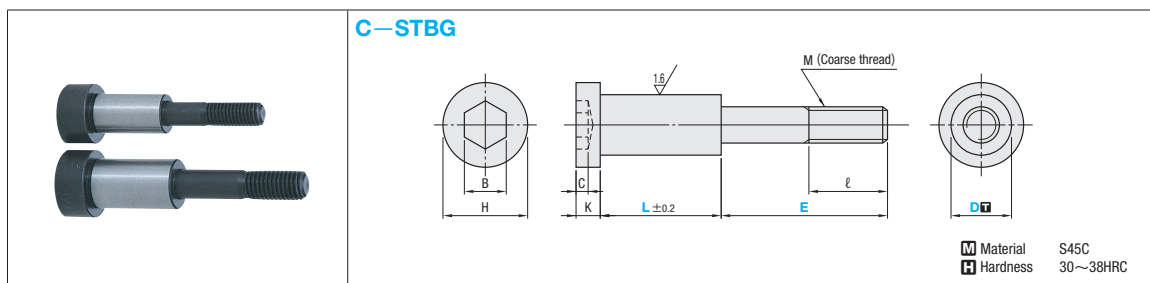

D1		C	K	H	D	B	M	ℓ	Part No.		L	E
									Type	D		
10	0 -0.15	4	8	16	10	6	M 6	18	C-STBG	10	16	22
											21	27
											14	30
13	0 -0.15	4	10	18	13	8	M 8	24		13	19	35
											24	40
											15	35
16	0 -0.20	7	14	24	16	10	M10	26		16	20	40
											30	45
											20	45
20	0 -0.20	9	14	28	20	14	M12	30		20	30	50
											35	55
											31	60
25	0 -0.20	10	18	33	25	17	M16	38		25	41	65



Order

Part No. — L — E
C-STBG 13 — 14 — 30



Days to Ship 6 Days



Price

Order / Quote:

WOS: <https://in.misumi-ec.com/>
TEL: +91-124-468-8800 E-mail: cs@misumi.co.in